


EuropacPRO Front Panel for 19" Module Support, 3 U, 84 HP, 2.5 mm, Al, Front Anodized, Rear Conductive

KATALOGNUMMER

24563-096

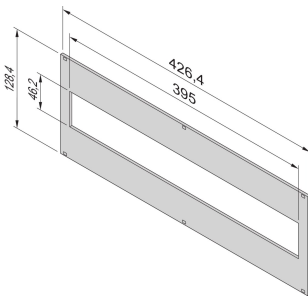

Front panel with cut-out in accordance with DIN 43880 (for power distribution modules).

CERTIFICERINGER



FUNKTIONER

Front panel with cut-out conforming to DIN 43880 (for power distribution modules)

Height 3 U, width 84 HP

PRODUKTEGENSKABER

Product Type: Front Panel

Produktfamilie: EuropacPRO

Accessory Type: Front panel

Mounting: Screw-on Front

Materiale: Aluminium

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: No

Rack Height: 3U

Højde: 128.4mm

Rack Width: 84HP

Bredde: 426.4mm

Dybde: 2.5mm

Pakke mængde: 1

Finish: Anodized; Passivated

Net Weight: 0.38kg

YDERLIGERE PRODUKTOPLYSNINGER

2 Plastic cover strips are included in the form of delivery.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE