


Hood for 19" module support

KATALOGNUMMER

24564-100

Hood to cover the rear side of 19" module support.

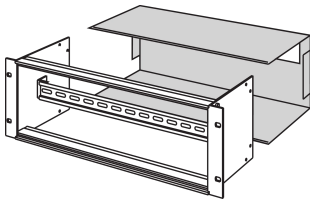

CERTIFICERINGER



FUNKTIONER

For assembly at rear on 19" module supports

Rear cut out for cable entry (351 x 40mm) cover through two brush strips

Rear hood prepared for grounding kit

Brush strip (self-adhesive): Plastic PVC (RAL7032), Bristle: Nylon black

PRODUKTEGENSKABER

Product Type: Cover

Produktfamilie: EuropacPRO

Type: Rear Hood

Works With: Subracks

Rack Height: 3U

Højde: 132.5mm

Rack Width: 84HP

Bredde: 431.5mm

Dybde: 88.3mm

Materiale: Aluminium

Pakke mængde: 1

Net Weight: 0.83kg

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE