


RatiopacPRO 19" Tower Case, Retrofittable Shielding, Front Trim, 4 U, 84 HP, 495 mm

KATALOGNUMMER

24571-395

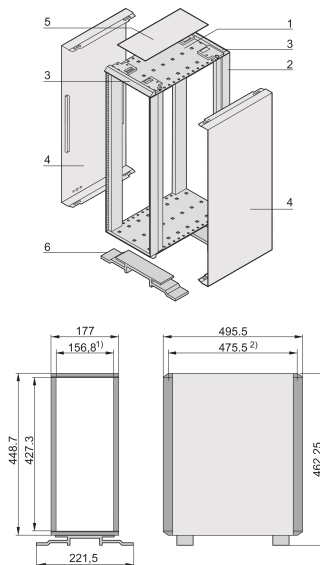

The nVent SCHROFF RatiopacPRO tower case provides electronics protection for 19" assemblies. This flexible and robust case is simple to convert from desktop to a 19" rack mount case and includes four different style options. This version of the case provides a sleek design and feet for desktop applications.

CERTIFICERINGER



FUNKTIONER

Case based on RatiopacPRO with case feet

Mounting space 4 U, 84 HP, depth 475 mm

Retrofittable EMC shielding

Symmetrical design, identical front and rear side

Conforms with DIN EN 62368-1

PRODUKTEGENSKABER

Product Type: Case

Produktfamilie: RatiopacPRO

Type: Tower

Rack Height: 4U

Højde: 177mm

Usable Height: 156.8mm

Rack Width: 84HP

Bredde: 448.9mm

Usable Width: 432mm

Dybde: 495.5mm

EMC Shielding: No (Retrofittable)

Static Load: 25kg

Beskyttelsesgrad: IP20

Front Frame Construction: Side Trim; Horizontal Rails

Cooling Option: No

Complies With: IEC 60297-3-101; IEC 60297-3-102; IEEE 1101.1; IEEE 1101.10; IEEE 1101.11

Pakke mængde: 1

Finish: Passivated; Struktur Pulvermaling

Materiale: Aluminium

Net Weight: 4kg

YDERLIGERE PRODUKTOPLYSNINGER

Modifications (special colours or sizes).

Custom solutions (cut-outs in top cover, base plate or side panels).

Assembly service from 1 piece.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE