


CPCI System for Pluggable PSU, Horizontal, 2 U, 4 Slot

KATALOGNUMMER

24579-082

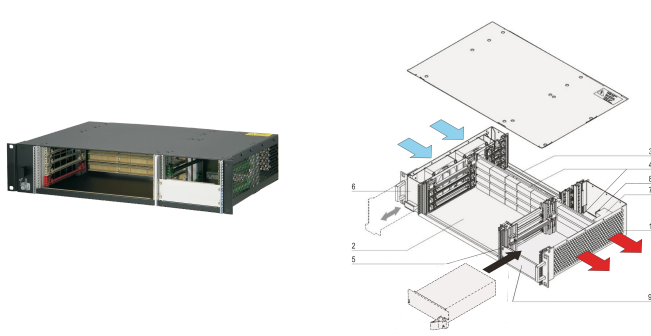

2 U CompactPCI System with horizontal Card Cage for four 6 U Boards, four RTM Boards and one CompactPCI 3 U Pluggable Power Supply. Option to assemble a second pluggable Power Supply.

CERTIFICERINGER



FUNKTIONER

In accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; backplane in accordance with PICMG 2.0 rev. 3.0

System with horizontal card cage. Board format Front: 6 U, 160 mm deep; Rear I/O: 6 U, 80 mm deep

Backplane (signal and power backplane in one unit) 4 slot, 6 U, 64 bit System slot left, Power connector (2 x P 47)

Heat dissipation by hot-swap fan unit (airflow left to right)

Prepared for the assembly of a 19" CompactPCI power supply (3 U, 8 HP)

PRODUKTEGENSKABER

Product Type: System

Number of Slots: 4

Type: 19" Rack Mount

Backplane Type: 6 U CompactPCI

Data Transfer: 64-bit PCI Bus

Power per Slot: 40W

Indgangsspænding AC: 100 – 240V

Airflow Direction: Left to Right

Rack Height: 2U

Power Supply Type: (1) Pluggable PSU

Power Supply Included: No

Rear I/O: Yes

Complies With: PICMG 2.0 R3.0

Dybde: 275mm

Højde: 88.1mm

Bredde: 449mm

Net Weight: 7.82kg

Pakke mængde: 1

YDERLIGERE PRODUKTOPLYSNINGER

Modified systems available on request.

48 VDC version on request.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unkladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE