


Front Panel, Unshielded, Cutout for Coax Connectors, 2.5 mm, Al, Front Anodized, Rear Conductive

KATALOGNUMMER

30118-355

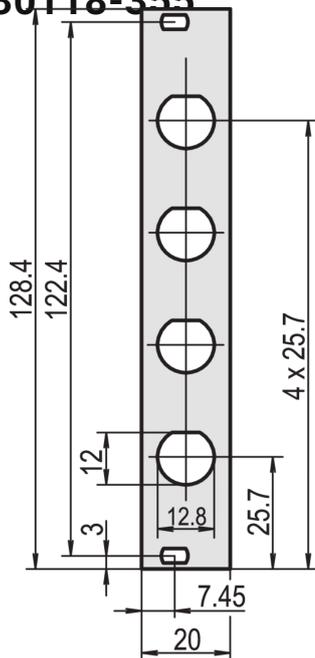

Aluminum, 2.5 mm, front anodized, conductive, unshielded version.

CERTIFICERINGER



FUNKTIONER

Al, 2.5 mm, front anodized, conductive

3 U, 4 HP

PRODUKTEGENSKABER

Product Type: Front Panel

Type: Front Panel without Handle

Accessory Type: Front panel

Mounting: Screw-on Front

EMC Shielding: No

Materiale: Aluminium

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: No

Rack Height: 3U

Højde (H): 128.4mm

Rack Width: 4HP

Bredde (W): 19.98mm

Dybde (D): 2.5mm

Complies With: IEC 60297-3-101; IEEE 1101.1/10

Pakke mængde: 1


Finish: Anodized; Passivated

Net Weight: 0.013kg

YDERLIGERE PRODUKTOPLYSNINGER

Please order fixing material (sleeves, collar screws) separately.

DIAGRAMS

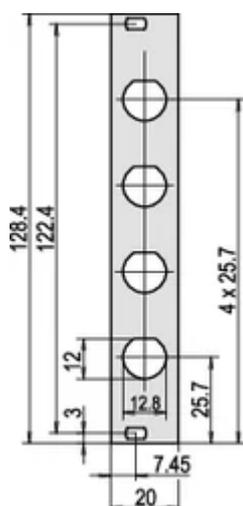

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unndladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE