


## Horizontal Rail, Rear, Type L-MZ, Light, With Z-Rail, 84 HP

**KATALOGNUMMER**

**34560-884**

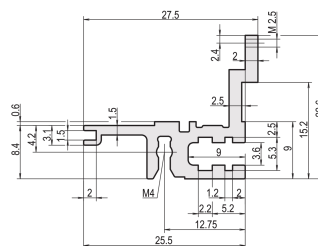

### Combinations of horizontal rails and side panels

|                    |                                                                                     | + <sup>1</sup> can be combined |                                                                                     | + combination not recommended |                                                                                     |           |                                                                                     |             |
|--------------------|-------------------------------------------------------------------------------------|--------------------------------|-------------------------------------------------------------------------------------|-------------------------------|-------------------------------------------------------------------------------------|-----------|-------------------------------------------------------------------------------------|-------------|
| 100% / 1.0         |  | -                              | +                                                                                   | +                             | +                                                                                   | +         | recommended for support                                                             |             |
|                    |  | +                              | recommended for flexible (not for support)                                          | +                             | recommended for heavy duty (not recommended for support)                            | +         | +                                                                                   |             |
| 100% / 1.0         |  | +                              | recommended for light                                                               | +                             | recommended for flexible                                                            | -         | -                                                                                   |             |
|                    |  | +                              | +                                                                                   | -                             | -                                                                                   | -         | -                                                                                   |             |
| Horizontal rail    |  | Light + L                      |  | Chandelier + L                |  | Heavy + R |  | Support + R |
| Aluminum extrusion |                                                                                     |                                |                                                                                     |                               |                                                                                     |           |                                                                                     |             |

The horizontal rail, type light with MZ enables the use of DIN connectors. The connectors are in accordance with EN 60603-2.

## CERTIFICERINGER



## FUNKTIONER

For directly mounting connectors complying with EN 60603 (DIN 41612)

With Z-rail for low mechanical load (L-MZ)

Aluminum extrusion, anodized finish, conductive contact surface

## PRODUKTEGENSKABER

Rack Width: 84HP

Pakke mængde: 1

Finish: Anodized

Length: 431.8mm

Materiale: Aluminium

Produktfamilie: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO

Product Type: Horizontal Rail

Type: Light, MZ

Works With: Subracks; Cases

Net Weight: 0.14kg

## YDERLIGERE PRODUKTOPLYSNINGER

Delivery is in standard pack multiples. Pricing is per individual item.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE