


Novastar Mobile Plinth

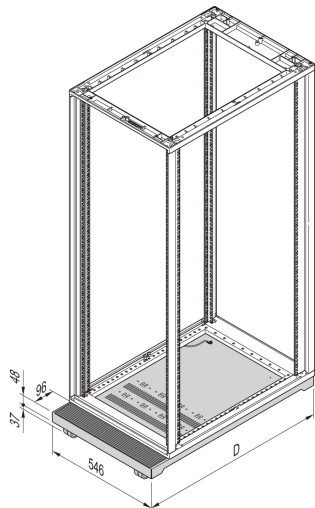

Aluminum mobile base plinth with load capacity of 200 kg, for aluminum cabinets with 600 mm breadth.

CERTIFICERINGER



FUNKTIONER

St, 2 mm

4 castors

Rubber mat, 3 mm

Load-carrying capacity 200 kg

Base/plinth height H = 100 mm

SPECIFIKATIONER

Product Type: Cabinet/Rack Base

Material: Stål

Table 1/2

Katalognummer	Bredde	Dybde	Pakke mængde	Farve	Farvekode	Finish
---------------	--------	-------	--------------	-------	-----------	--------

27230-146	553mm	500mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
27230-148	553mm	800mm	1	Black Grey	RAL 7021	Struktur Pulvermaling
27230-147	553mm	600mm	1	Black Grey	RAL 7021	Struktur Pulvermaling

Table 2/2

Katalognummer	Type
27230-146	Base Plinth
27230-148	Base Plinth
27230-147	Base Plinth

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE