


Plug-In Unit U-Profile Front Panel for XL Handle

Front panel for XL handle. Shieldable with textile gasket. with or without cutout for a microswitch.

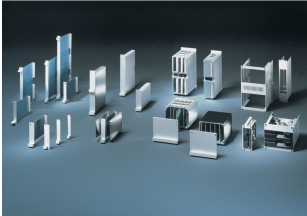

CERTIFICERINGER



FUNKTIONER

Al, front anodized, sides and rear conductive

Suitable for sleeve and collar screw

U-front profile, shieldable, for inserter/extractor handle, type XL

SPECIFIKATIONER

Materiale:	Aluminium
Finish:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Type:	Front Panel for Handle (PIU)
EMC Shielding:	No (Retrofittable)

Table 1/3

Katalognummer	Rack Width	Pakke mængde	Håndtagstype	Mounting	Gasket Type	Front Finish
30849-153	4HP	1	XL	Screw-on Front	Textile EMC	Anodized
30849-154	4HP	1	XL	Screw-on Front	Textile EMC	Anodized

Katalognummer	Rack Width	Pakke mængde	Håndtagstype	Mounting	Gasket Type	Front Finish
30849-158	12HP	1	XL	Screw-on Front	Textile EMC	Anodized
30849-155	8HP	1	XL	Screw-on Front	Textile EMC	Anodized
30849-157	12HP	1	XL	Screw-on Front	Textile EMC	Anodized
30849-156	8HP	1	XL	Screw-on Front	Textile EMC	Anodized

Table 2/3

Katalognummer	Rear Finish	Treated Edges	Complies With	Dybde (D)	Højde (H)	Rack Height
30849-153	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-154	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-158	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-155	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-157	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-156	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U

Table 3/3

Katalognummer	Bredde (W)
30849-153	20mm
30849-154	20mm
30849-158	60.6mm
30849-155	40.3mm
30849-157	60.6mm
30849-156	40.3mm

YDERLIGERE PRODUKTOPLYSNINGER

Delivery is exclusively in standard pack quantity, Please order EMC textile gasket and microswitch separately.

