


PropacPRO EMC Rear Panel, Full Width

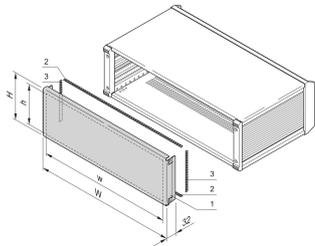

The EMC rear panel, full width for PropacPRO Case mounts to the frame of the case. It has no perforation. The shielding is done with textile EMC gaskets.

CERTIFICERINGER



FUNKTIONER

Alu panel, 1.5 mm, with fastener for Earthing / GND

Mounts on case (left, right)

Without perforation

SPECIFIKATIONER

Materiale:	Aluminium
Finish:	Anodized; Passivated
Works With:	Cases
Produktfamilie:	PropacPRO
Type:	Rear Panel
Product Type:	Side Panel

Table 1/1

Katalognummer	Rack Height	Rack Width	Pakke mængde
24576-247	3U	28HP	1
24576-244	2U	42HP	1
24576-258	6U	84HP	1
24576-248	3U	42HP	1

Katalognummer	Rack Height	Rack Width	Pakke mængde
24576-254	4U	84HP	1
24576-249	3U	63HP	1
24576-253	4U	63HP	1
24576-250	3U	84HP	1
24576-252	4U	42HP	1
24576-245	2U	63HP	1

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unkladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE