


PropacPRO Rear Panel, Full Width, Unshielded

The rear panel, full width for PropacPRO Case mounts to the frame of the case. With or without vented slots.

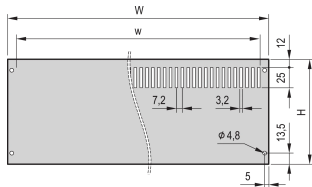

CERTIFICERINGER



FUNKTIONER

Alu panel, 2.0 mm (84 HP 2.5 mm)

Mounting with support bracket on case (right and left)

SPECIFIKATIONER

- Materiale:** Aluminium
- Finish:** Anodized
- Works With:** Cases
- Produktfamilie:** PropacPRO
- Type:** Rear Panel
- Product Type:** Side Panel

Table 1/2

Katalognummer	Rack Height	Rack Width	Design Feature	Pakke mængde
24576-153	4U	63HP	Perforated	1
24576-145	2U	63HP	Perforated	1
24576-050	3U	84HP	Non-Perforated	1
24576-149	3U	63HP	Perforated	1
24576-150	3U	84HP	Perforated	1

Katalognummer	Rack Height	Rack Width	Design Feature	Pakke mængde
24576-049	3U	63HP	Non-Perforated	1
24576-052	4U	42HP	Non-Perforated	1
24576-148	3U	42HP	Perforated	1
24576-045	2U	63HP	Non-Perforated	1
24576-152	4U	42HP	Perforated	1
24576-053	4U	63HP	Non-Perforated	1
24576-047	3U	28HP	Non-Perforated	1
24576-054	4U	84HP	Non-Perforated	1
24576-048	3U	42HP	Non-Perforated	1
24576-154	4U	84HP	Perforated	1
24576-146	2U	84HP	Perforated	1
24576-044	2U	42HP	Non-Perforated	1
24576-046	2U	84HP	Non-Perforated	1
24576-158	6U	84HP	Perforated	1
24576-147	3U	28HP	Perforated	1

Table 2/2

Katalognummer	Rack Height	Rack Width	Design Feature	Pakke mængde
24576-058	6U	84HP	Non-Perforated	1
24576-144	2U	42HP	Perforated	1

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE