


PSU Front Panel

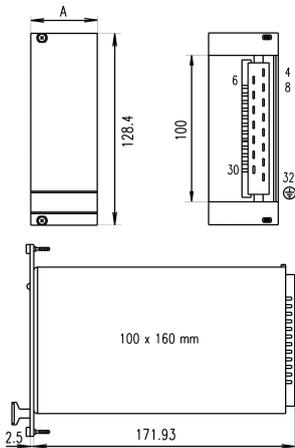

Front Panel for nVent SCHROFF 19" compatible Power Supply. Flat front panel with vertical grooves for stainless steel EMC Contact Strips.

CERTIFICERINGER



FUNKTIONER

Front Panel, Al, Front anodized, rear conductive, with vertical Slots for EMC Contact Strips

SPECIFIKATIONER

Accessory Type: Front panel

Table 1/2

Katalognummer	Materiale	Front Finish	Rear Finish	Treated Edges	Rack Height	Højde
21005-439	Aluminium	Anodized	Conductive	No	3U	128.4mm
21006-959	Aluminium	Anodized	Conductive	No	3U	128.4mm
21005-478	Aluminium	Anodized	Conductive	No	3U	128.4mm
31006-677	Aluminium	Anodized	Conductive	No	3U	128.4mm
21005-477	Aluminium	Anodized	Conductive	No	3U	128.4mm

Katalognummer	Materiale	Front Finish	Rear Finish	Treated Edges	Rack Height	Højde
21006-954	Aluminium	Anodized	Conductive	No	3U	128.4mm
21005-470	Aluminium	Anodized	Conductive	No	3U	128.4mm
21006-955	Aluminium	Anodized	Conductive	No	3U	128.4mm
21005-476	Aluminium	Anodized	Conductive	No	3U	128.4mm
21006-945	Aluminium	Anodized	Conductive	No	3U	128.4mm
21006-956	Aluminium	Anodized	Conductive	No	3U	128.4mm
21005-474	Aluminium	Anodized	Conductive	No	3U	128.4mm
21005-451	Aluminium	Anodized	Conductive	No	3U	128.4mm
21006-957	Aluminium	Anodized	Conductive	No	3U	128.4mm
21006-943	Aluminium	Anodized	Conductive	No	3U	128.4mm
21005-475	Aluminium	Anodized	Conductive	No	3U	128.4mm
21005-473	Aluminium	Anodized	Conductive	No	3U	128.4mm

Table 2/2

Katalognummer	Rack Width	Bredde	Dybde	Pakke mængde	Finish
21005-439	14HP	7078mm	2.5mm	1	Anodized
21006-959	3HP	14.9mm	2.5mm	1	Anodized
21005-478	14HP	70.78mm	2.5mm	1	Anodized
31006-677	8HP	40.3mm	2.5mm	1	Anodized
21005-477	10HP	50.46mm	2.5mm	1	Anodized
21006-954	6HP	30.14mm	2.5mm	1	Anodized
21005-470	6HP	30.14mm	2.5mm	1	Anodized
21006-955	6HP	30.14mm	2.5mm	1	Anodized
21005-476	6HP	30.14mm	2.5mm	1	Anodized
21006-945	8HP	40.3mm	2.5mm	1	Anodized
21006-956	6HP	30.14mm	2.5mm	1	Anodized
21005-474	14HP	7078mm	2.5mm	1	Anodized
21005-451	10HP	50.46mm	2.5mm	1	Anodized
21006-957	6HP	30.14mm	2.5mm	1	Anodized
21006-943	6HP	30.14mm	2.5mm	1	Anodized
21005-475	6HP	30.14mm	2.5mm	1	Anodized
21005-473	10HP	50.46mm	2.5mm	1	Anodized

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unndladelser af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE