


# Sleeves for M2.5

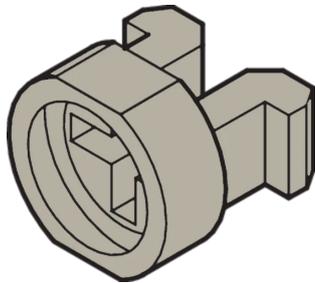

Sleeve guides the collar screw when fastening the front panel.

## CERTIFICERINGER



## FUNKTIONER

Sleeve guides the collar screw when fastening the front panel

Sleeve is inserted into the elongated hole of the front panel

## SPECIFIKATIONER

**Works With:** Front Panels

**Product Type:** Sleeve

Table 1/2

Katalognummer	Materiale	Finish	Farve	Pakke mængde	Farvekode	Dybde (D)
21100-886	Brass	Organic Top Coat		100		4.4mm
21100-662	Stainless Steel			100		4.4mm
21100-660	Brass	Nickel Plated		100		4.4mm
21100-591	Polyamide 6		Jet Black	100	RAL 9005	6.9mm
21100-464	Polyamide 6		Pebble Grey	100	RAL 7032	6.9mm
21100-659	Brass	Nickel Plated		10		

Katalognummer	Materiale	Finish	Farve	Pakke mængde	Farvekode	Dybde (D)
21100-661	Stainless Steel			10		
21100-885	Brass			10		

Table 2/2


Katalognummer	Højde (H)	Bredde (W)	Flammability Rating
21100-886	6mm	8mm	
21100-662	6mm	8mm	
21100-660	6mm	8mm	
21100-591	6mm	6.8mm	UL® 94V-2
21100-464	6mm	6.8mm	UL® 94V-2
21100-659			
21100-661			
21100-885			

## YDERLIGERE PRODUKTOPLYSNINGER

Metal sleeves on the partial front panels must be pressed in.

All sleeves can be used for front panel > 2 HP.

## DIAGRAMS

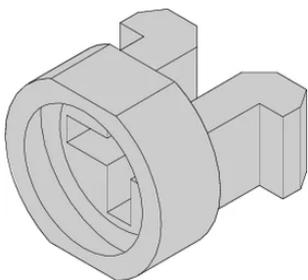

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**