


Varistar CP Slide Rail

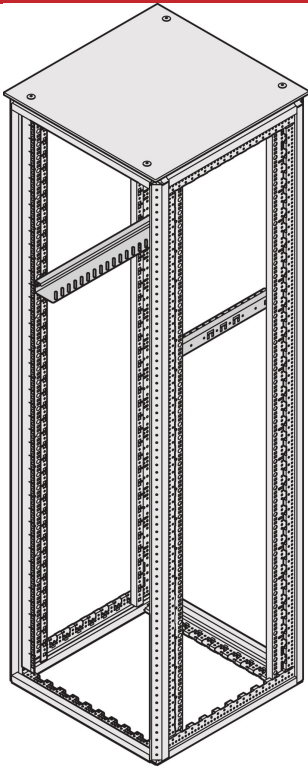

Mounts on four 19" slide mounts with 25/100 kg weight capacity.

CERTIFICERINGER



FUNKTIONER

Mounts on four 19" slide mounts

Wide support surface (48 mm)

Can be fitted in 1 U increments (attach and screw into place)

SPECIFIKATIONER

Product Type: Slide Rail

Materiale: Stål

Table 1/2

Katalognummer	Static Load	Pakke mængde	Finish	Højde	Length	Works With
23130-096	25kg	2	Aluminum-Zinc Plated	500mm	456mm	Varistar CP
23130-099		2	Aluminum-Zinc Plated			Varistar CP
23130-116	100kg	2	Aluminum-Zinc Plated	200mm	156mm	Varistar CP
23130-120	100kg	2	Aluminum-Zinc Plated	740mm	699mm	Varistar CP
23130-118	100kg	2	Aluminum-Zinc Plated	500mm	458mm	Varistar CP
23130-098	25kg	2	Aluminum-Zinc Plated	740mm	699mm	Varistar CP
23130-097	25kg	2	Aluminum-Zinc Plated	700mm	656mm	Varistar CP
23130-119	100kg	2	Aluminum-Zinc Plated	700mm	658mm	Varistar CP
23130-123	100kg	10	Aluminum-Zinc Plated	500mm	458mm	Varistar CP
23130-101	25kg	10	Aluminum-Zinc Plated	500mm	456mm	Varistar CP
23130-124	100kg	10	Aluminum-Zinc Plated	700mm	658mm	Varistar CP
23130-102	25kg	10	Aluminum-Zinc Plated	700mm	656mm	Varistar CP
23130-125	100kg	10	Aluminum-Zinc Plated	740mm	699mm	Varistar CP
23130-103	25kg	10	Aluminum-Zinc Plated	740mm	699mm	Varistar CP
23130-126		10	Aluminum-Zinc Plated			Varistar CP

Table 2/2

Katalognummer	Pakkeenhed	Certificeringer
23130-096	Pair	RoHS
23130-099	Pair	
23130-116		RoHS
23130-120		RoHS
23130-118		RoHS
23130-098	Pair	RoHS

Katalognummer	Pakkeenhed	Certificeringer
23130-097	Pair	RoHS
23130-119		RoHS
23130-123		RoHS
23130-101		RoHS
23130-124		RoHS
23130-102		RoHS
23130-125		RoHS
23130-103		RoHS
23130-126		RoHS

YDERLIGERE PRODUKTOPLYSNINGER

For mounting in the cabinet the 19" panel/slide mounts must be fitted front and rear.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE