


Swing Frame for 600 mm Width

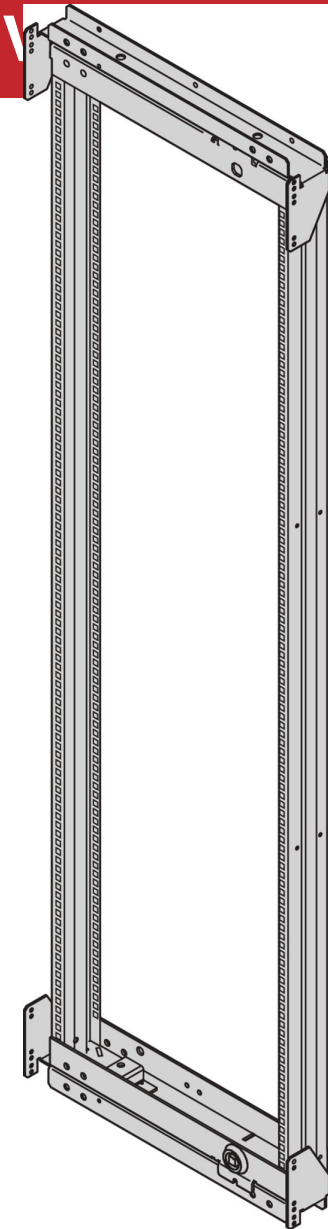

The 19" swing frame allows the installation of sub-racks while simultaneously making wiring at the rear accessible.

Varistar CP swing frame comes with 150 KG load capacity, 120° movement and flexible pivot point.

FUNKTIONER

For full height or partial-height mounting

Pivot point can be selected right or left

Can accommodate 19" chassis and 19" subracks (maximum depth 200 mm)

120° hinge, square locks including 2 keys

Load-carrying capacity 150 kg

SPECIFIKATIONER

Bredde:	600mm
Product Type:	Cabinet/Rack Frame
Materiale:	Stål

Table 1/2

Katalognummer	Rack Height	Pakke mængde	Farve	Farvekode	Finish	Højde
21630-668	24U	1	Black Grey	RAL 7021	Struktur Pulvermaling	1200mm
21630-678	47U	1	Black Grey	RAL 7021	Struktur Pulvermaling	2200mm
21630-676	42U	1	Black Grey	RAL 7021	Struktur Pulvermaling	2000mm
21630-674	38U	1	Black Grey	RAL 7021	Struktur Pulvermaling	1800mm
21630-672	33U	1	Black Grey	RAL 7021	Struktur Pulvermaling	1600mm
21630-670	29U	1	Black Grey	RAL 7021	Struktur Pulvermaling	1400mm

Table 2/2

Katalognummer	Beskyttelsesgrad
21630-668	IP20
21630-678	IP20
21630-676	IP20
21630-674	IP20
21630-672	IP20
21630-670	IP20

YDERLIGERE PRODUKTOPLYSNINGER

By aid of depth members 19" swing frames can be assembled directly on the cabinet frame or in depth-adjustable increments of 50 mm.

Please purchase the grounding kit separately.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unkladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE