


Swing Frame for 800 mm Width

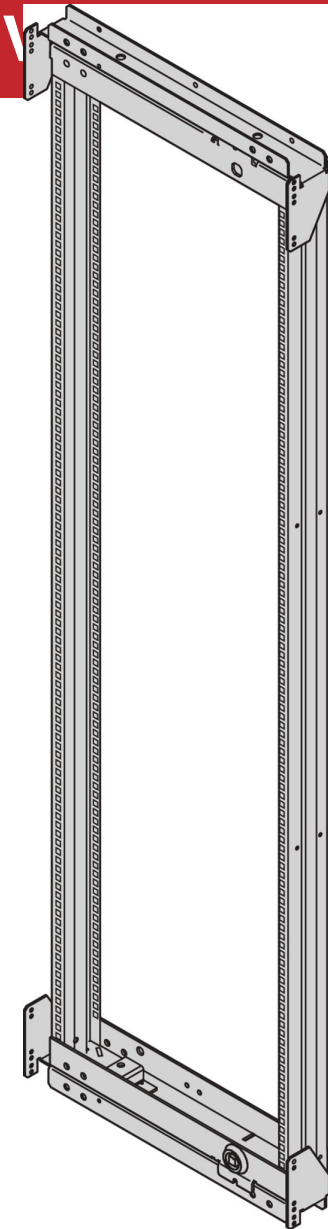

The 19" swing frame allows the installation of sub-racks while simultaneously making wiring at the rear accessible.

Varistar CP swing frame comes with 150 KG load capacity, 120° / 160° movement and flexible pivot point.

FUNKTIONER

For full height or partial-height mounting

Pivot point can be selected right or left

Can accommodate 19" chassis and 19" subracks

120° / 160° hinge, square locks including 2 keys

Load-carrying capacity 150 kg

Usable height within the swing frame is 4U lesser than the frame height to which the swing frame is attached to.

SPECIFIKATIONER

Bredde:	800mm
Product Type:	Cabinet/Rack Frame
Materiale:	Stål

Table 1/2

Katalognummer	Angle	Rack Height	Pakke mængde	Farve	Farvekode	Finish
21630-681	160° min	29U	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-669	120° min	24U	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-685	160° min	47U	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-675	120° min	38U	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-677	120° min	42U	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-684	160° min	42U	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-679	120° min	47U	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-673	120° min	33U	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-683	160° min	38U	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-680	160° min	24U	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-682	160° min	33U	1	Black Grey	RAL 7021	Struktur Pulvermaling
21630-671	120° min	29U	1	Black Grey	RAL 7021	Struktur Pulvermaling

Table 2/2

Katalognummer	Højde	Beskyttelsesgrad
21630-681	1400mm	IP20
21630-669	1200mm	IP20
21630-685	2200mm	IP20
21630-675	1800mm	IP20

Katalognummer	Højde	Beskyttelsesgrad
21630-677	2000mm	IP20
21630-684	2000mm	IP20
21630-679	2200mm	IP20
21630-673	1600mm	IP20
21630-683	1800mm	IP20
21630-680	1200mm	IP20
21630-682	1600mm	IP20
21630-671	1400mm	IP20

YDERLIGERE PRODUKTOPLYSNINGER

By aid of depth members 19" swing frames can be assembled directly on the cabinet frame or in depth-adjustable increments of 50 mm.

Please purchase the grounding kit separately.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE