

ADJ Clamp for PVC Pipe, HD, 80 DN, 82 mm OD, M8 Rod

CATALOG NUMBER

ADJ080PVCHDG



FEATURES

Adjustable suspension of horizontal and vertical pipe services

Double bolted

PRODUCT ATTRIBUTES

Color: White

Finish: Hot-Dip Galvanized

NB/DN: 80

Outer Diameter (OD): 82 mm

Rod Size (RS): M8

Height (H): 141 mm

Width (W): 20 mm

Thickness (T): 3 mm


A: 48 mm

Screw Diameter (Sc): 8

Screw Length (L): 25mm

Static Load: 1500N

DIAGRAMS

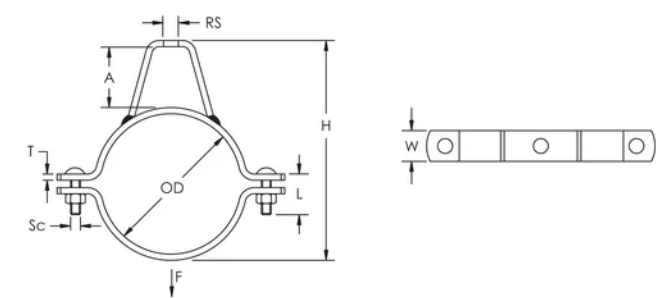

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

