

ADJ Clamp for PVC Pipe, Polyester, 300 DN, 316 mm OD, M12 Rod

CATALOG NUMBER

ADJ300PVCPPC



FEATURES

Adjustable suspension of horizontal and vertical pipe services

Double bolted

PRODUCT ATTRIBUTES

Color: White

Finish: Polyester

NB/DN: 300

Outer Diameter (OD): 316 mm

Rod Size (RS): M12

Height (H): 411 mm

Width (W): 40 mm

Thickness (T): 5 mm


A: 60 mm

Screw Diameter (Sc): 12

Screw Length (L): 50mm

Static Load: 7500N

DIAGRAMS

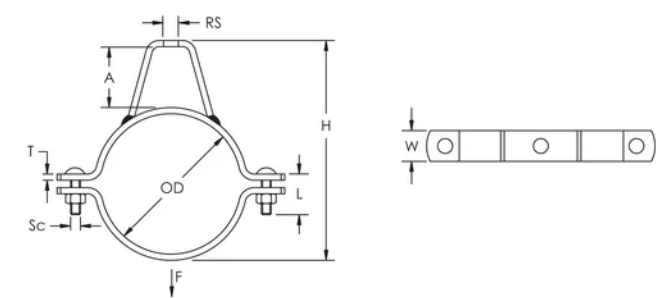

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

