

SOB Pipe Clamp for PVC Pipe, 225 DN, 251 mm OD

CATALOG NUMBER

SOB225PVCPPC



FEATURES

Stand off bracket for vertical pipe services

Attaches directly to horizontal or vertical structural member

Double bolted

PRODUCT ATTRIBUTES

Material: Steel

Finish: Polyester

Color: White

NB/DN: 225

Outer Diameter (OD): 251 mm

A: 368 mm

Width (W): 40 mm

Thickness (T): 6 mm


Hole Size (HS): 13.5 mm

Screw Diameter (Sc): 12

Screw Length (L): 40mm

Static Load: 6000N

DIAGRAMS

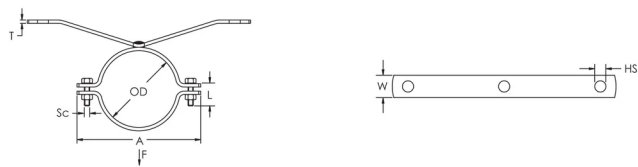

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

