

512 nVent CADDY EZ Riser for Close Quarters, 1 1/2" Pipe, 1.9" OD


CATALOG NUMBER

5120150EG



The 512 nVent CADDY EZ Riser for Close Quarters is a quick-closing pipe clamp, ideal for vertical pipe in tight spaces. This innovative solution is designed for situations where a full-sized clamp would not fit—typically, when a pipe is close to the corner of a room. Ready-to-use out of the box, this solution has slotted holes to simplify assembly and eliminate loose hardware. Due to the serrated washer-head design, installers can easily assemble the EZ Riser for Close Quarters with just a single tool.

CERTIFICATIONS

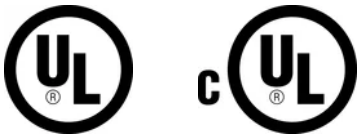

FEATURES

Only one tool needed to tighten due to serrated wash-heads

Short ears allow for use in confined spaces or corners

Conforms with Federal Specification WW-H-171 (Type 8), Manufacturers Standardization Society (MSS) SP-58 (Type 8)

PRODUCT ATTRIBUTES

Material: Steel

Finish: Electrogalvanized

Pipe Size: 1 1/2"

NB/DN: 40

Outer Diameter (OD): 48 mm


Hole Size (HS): 11 mm

A: 155.57 mm

B: 25.4 mm

Static Load: 1100N

DIAGRAMS

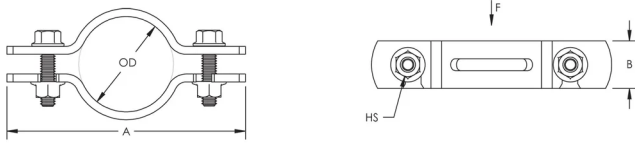

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

