

Front Panel, Flat, Unshielded, D-Sub Cutouts



Flat front panel with cutout for D-Sub connectors.
Unshielded version.

CERTIFICATIONS



FEATURES

Non-shielded version

Al, 2.5 mm, front anodized, rear conductive

SPECIFICATIONS

| | |
|------------------------|----------------------------|
| Rack Height: | 3U |
| Rack Width: | 4HP |
| Material: | Aluminum |
| Finish: | Anodized; Passivated |
| Accessory Type: | Front panel |
| Product Type: | Front Panel |
| Type: | Front Panel without Handle |

Table 1/2

| Catalog Number | Package Quantity | Mounting | Front Finish | Rear Finish | Number of Pins | Treated Edges |
|----------------|------------------|----------------|--------------|-------------|----------------|---------------|
| 30118-343 | 1 | Screw-on Front | Anodized | Conductive | (1) 25 | No |
| 30118-345 | 1 | Screw-on Front | Anodized | Conductive | (2) 15 | No |
| 30118-344 | 1 | Screw-on Front | Anodized | Conductive | (2) 9 | No |
| 30118-346 | 1 | Screw-on Front | Anodized | Conductive | (2) 25 | No |
| 30118-347 | 1 | Screw-on Front | Anodized | Conductive | (3) 9 | No |
| 30118-342 | 1 | Screw-on Front | Anodized | Conductive | (1) 15 | No |
| 30118-341 | 1 | Screw-on Front | Anodized | Conductive | (3) 9 | No |

Table 2/2

| Catalog Number | Complies With | Depth (D) | EMC Shielding | Height (H) | Width (W) |
|----------------|------------------------------------|-----------|---------------|------------|-----------|
| 30118-343 | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm | No | 128.4mm | 19.98mm |
| 30118-345 | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm | No | 128.4mm | 19.98mm |
| 30118-344 | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm | No | 128.4mm | 19.98mm |
| 30118-346 | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm | No | 128.4mm | 19.98mm |
| 30118-347 | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm | No | 128.4mm | 19.98mm |
| 30118-342 | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm | No | 128.4mm | 19.98mm |
| 30118-341 | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm | No | 128.4mm | 19.98mm |









ADDITIONAL PRODUCT DETAILS

Delivery is in standard pack multiples. Pricing is per individual item.

Please order fixing material (sleeves, collar screws) separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

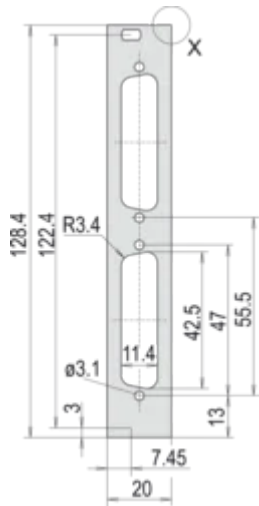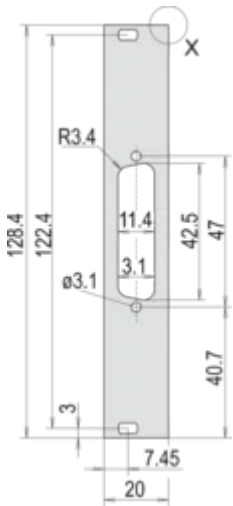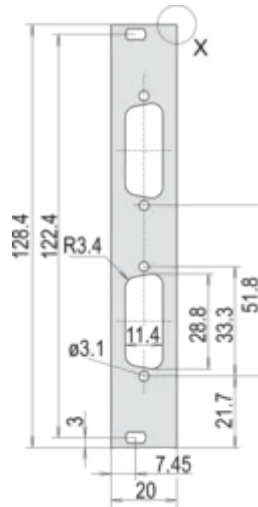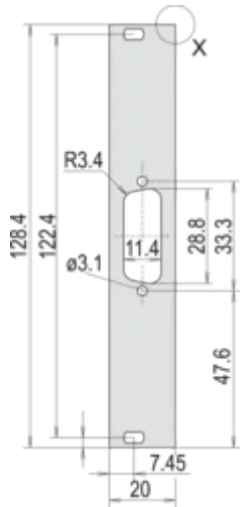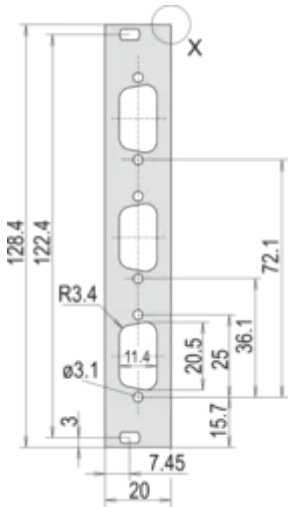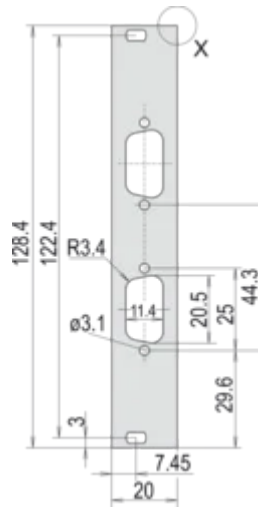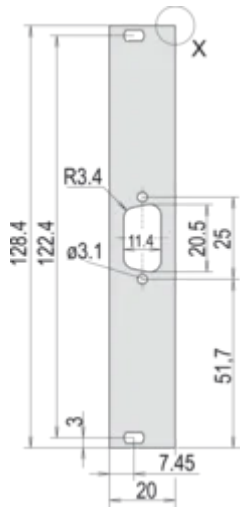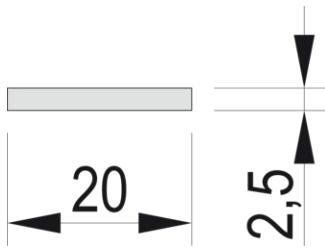

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE