

# FCS Height Adjustable Loop Hanger



## CERTIFICATIONS

FM Approved, Pipe Hanger Components



## FEATURES

Recommended for the suspension of stationary non-insulated fire sprinkler pipe

Redesigned strap and cup nut minimize friction for easier adjustment up and down the threaded rod (1/2" to 4" sizes)

Formed tips on the upper strap simplify disassembly and reassembly of the hanger

Rolled edges on the strap help to guide the pipe through, limiting binding and damage to metal or plastic pipe

Package includes all necessary hardware for installation

## SPECIFICATIONS

**Finish:** Electrogalvanized

**Material:** Steel

Table 1/2

| Catalog Number | Article Number | NB/DN | Outer Diameter (OD) | Rod Size (RS) | Width (W) | A     |
|----------------|----------------|-------|---------------------|---------------|-----------|-------|
| FCS0100M10     | 597969         | 25    | 34 mm               | M10           | 10 mm     | 87 mm |
| FCS0125M10     | 597971         | 32    | 43 mm               | M10           | 10 mm     | 91 mm |
| FCS0150M8      | 597965         | 40    | 48 mm               | M8            | 10 mm     | 97 mm |


| CatalogNumber | Article Number | NB/DN | Outer Diameter (OD) | Rod Size (RS) | Width (W) | A      |
|---------------|----------------|-------|---------------------|---------------|-----------|--------|
| FCS0100M8     | 597963         | 25    | 34 mm               | M8            | 10 mm     | 85 mm  |
| FCS0250M10    | 597974         | 65    | 76 mm               | M10           | 10 mm     | 142 mm |
| FCS0200M8     | 597966         | 50    | 60 mm               | M8            | 10 mm     | 112 mm |
| FCS0075M10    | 597968         | 20    | 27 mm               | M10           | 10 mm     | 76 mm  |
| FCS0150M10    | 597972         | 40    | 48 mm               | M10           | 10 mm     | 99 mm  |
| FCS0300M10    | 597975         | 80    | 89 mm               | M10           | 10 mm     | 164 mm |
| FCS0200M10    | 597973         | 50    | 60 mm               | M10           | 10 mm     | 114 mm |
| FCS0400M10    | 597976         | 100   | 114 mm              | M10           | 10 mm     | 206 mm |
| FCS0125M8     | 597964         | 32    | 43 mm               | M8            | 10 mm     | 89 mm  |
| FCS0600M12    | 597978         | 150   | 165 mm              | M12           | 15 mm     | 272 mm |
| FCS0500M12    | 597977         | 125   | 140 mm              | M12           | 15 mm     | 227 mm |
| FCS0800M16    | 597979         | 200   | 219 mm              | M16           | 25 mm     | 349 mm |
| FCS1000M20    | 597981         | 250   | 273 mm              | M20           | 25 mm     | 480 mm |

Table 2/2

| Catalog Number | Article Number | B     | C     | Static Load | Wrench Size | Certifications                                    |
|----------------|----------------|-------|-------|-------------|-------------|---------------------------------------------------|
| FCS0100M10     | 597969         | 36 mm | 19 mm | 2000N       | 15 mm       | VdS G4050054, FM Approved, Pipe Hanger Components |
| FCS0125M10     | 597971         | 36 mm | 15 mm | 2000N       | 15 mm       | VdS G4050054, FM Approved, Pipe Hanger Components |
| FCS0150M8      | 597965         | 41 mm | 17 mm | 2000N       | 13 mm       | VdS G4050054                                      |
| FCS0100M8      | 597963         | 36 mm | 19 mm | 2000N       | 13 mm       | VdS G4050054                                      |
| FCS0250M10     | 597974         | 68 mm | 30 mm | 3500N       | 15 mm       | VdS G4050054, FM Approved, Pipe Hanger Components |
| FCS0200M8      | 597966         | 50 mm | 20 mm | 2000N       | 13 mm       | VdS G4050054                                      |
| FCS0075M10     | 597968         | 31 mm | 17 mm | 2000N       | 15 mm       | FM Approved, Pipe Hanger Components, VdS G4050054 |
| FCS0150M10     | 597972         | 41 mm | 17 mm | 2000N       | 15 mm       | FM Approved, Pipe Hanger Components, VdS G4050054 |

| CatalogNumber | Article Number | B      | C      | Static Load | Wrench Size | Certifications                                    |
|---------------|----------------|--------|--------|-------------|-------------|---------------------------------------------------|
| FCS0300M10    | 597975         | 83 mm  | 39 mm  | 3500N       | 15 mm       | VdS G4050054, FM Approved, Pipe Hanger Components |
| FCS0200M10    | 597973         | 50 mm  | 20 mm  | 2000N       | 15 mm       | VdS G4050054, FM Approved, Pipe Hanger Components |
| FCS0400M10    | 597976         | 112 mm | 55 mm  | 3500N       | 15 mm       | VdS G4050054, FM Approved, Pipe Hanger Components |
| FCS0125M8     | 597964         | 36 mm  | 15 mm  | 2000N       | 13 mm       | VdS G4050054                                      |
| FCS0600M12    | 597978         | 146 mm | 63 mm  | 5000N       | 18 mm       | FM Approved, Pipe Hanger Components, VdS G4050054 |
| FCS0500M12    | 597977         | 114 mm | 44 mm  | 5000N       | 18 mm       | VdS G4050054, FM Approved, Pipe Hanger Components |
| FCS0800M16    | 597979         | 184 mm | 75 mm  | 8500N       | 24 mm       | FM Approved, Pipe Hanger Components, VdS G4050054 |
| FCS1000M20    | 597981         | 279 mm | 143 mm | 10000N      | 30 mm       | VdS G4050054                                      |

## DIAGRAMS

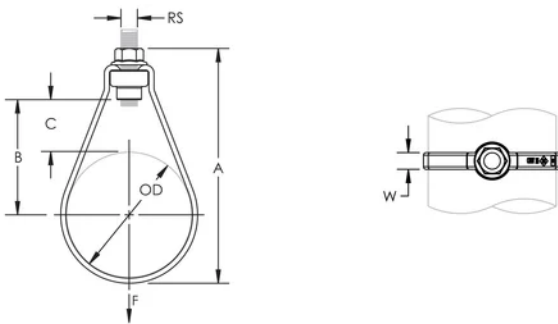

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

