


# Open Frame Panel Adapter

## Data Solutions

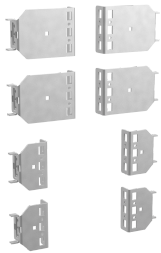

The Open-Frame Panel Adapter adapts a 23-inch open-frame rack to accept 19-inch equipment. The offset provides a flush mounting surface. Please note these are furnished in pairs.

### FEATURES

The Open-Frame Panel Adapter adapts a 23-inch open-frame rack to accept 19-inch equipment

The offset provides a flush mounting surface

Please note these are furnished in pairs

### SPECIFICATIONS

Table 1/1

| Catalog Number | Article Number | Material   | Finish      | Thickness | Rack Units |
|----------------|----------------|------------|-------------|-----------|------------|
| ERB1U2319      | 21939          | Mild Steel | Zinc Plated | 1.9mm     | 1U         |
| ERB3U2319      | 21949          | Mild Steel | Zinc Plated | 1.9mm     | 3U         |
| ERB5U2319      | 21959          | Mild Steel | Zinc Plated | 1.9mm     | 5U         |

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**