 


Theft-Deterrent Grounding Busbar, Flange Mount Assembly


Data Solutions

CATALOG NUMBER

TDSGABC14



CERTIFICATIONS

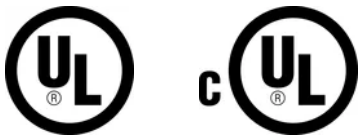

FEATURES

Mounts to a typical structural beam flange on a telecom tower without cutting or drilling the flange

Accepts standard telecommunication grounding lugs (lugs not included)

Includes 14 Standard Spacers (TDSGAS)

PRODUCT ATTRIBUTES

Material: Copper; Stainless Steel 18-8 (EN 1.4305); Nylon

Finish: Tinned

Spacer Thickness: 6.4mm

Length 1 (L1): 266mm

Length 2 (L2): 101.6mm

Depth (D): 54.1mm

Height (H): 69mm

A: 25.4mm


Flange Thickness (FT): 6.4 – 25.4mm

Thread Size 1 (TS1): 3/8" UNC

Thread Size 2 (TS2): 5/16" UNC

Thread Size 3 (TS3): 5/16" UNC

DIAGRAMS

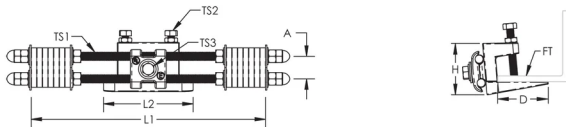

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE