

nVent CADDY Cat CM U-Hook, Strut Mount, 203 mm

Data Solutions

CATALOG NUMBER

CAT200CM



CERTIFICATIONS



FEATURES

- Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic
- Integrated quick-attach T-nut allows U-Hooks to be quickly mounted to strut
- System offers a convenient pathway for wires and cables
- Specially designed U-Hooks have large-diameter, rounded support surfaces
- Rounded edges help prevent over-bending and kinking of cables
- Ideal for retrofit applications where cable runs need to be routed around existing building infrastructure
- Compliant with NEC® and ANSI®/TIA structured cabling systems standards

PRODUCT ATTRIBUTES

Article Number: 181982

Material: Steel

Finish: Electrogalvanized

Included Components: Quick-Attach T-Nut

Cable Capacity, Cat 5e: 450

Cable Capacity, Cat 6: 350

Cable Capacity, Cat 6A: 215


A: 203mm

Area: 533mm²

Hole Size (HS): 9.5mm

Static Load: 440N

DIAGRAMS

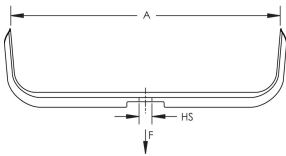

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE