


# Novastar Base/Plinth

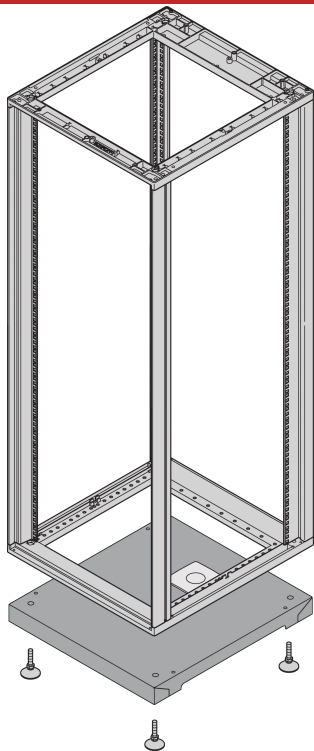

Base Plate for Rear Cable Ducting which cut out for cable management. Opening is covered with plastic. Accessory brush strip can build in.

## CERTIFICATIONS



## FEATURES

Static load-carrying capacity 400 kg

Adjustable feet, height 57 mm ... 67 mm

St, 1.5 mm, RAL 7021

Cable ducting 110 x 76 mm

Incl. GND/earthing

## SPECIFICATIONS

---

|                      |                   |
|----------------------|-------------------|
| <b>Height:</b>       | 45mm              |
| <b>Product Type:</b> | Cabinet/Rack Base |
| <b>Material:</b>     | Steel             |

Table 1/2

| Catalog Number | Width  | Depth  | Package Quantity | Color      | Color Code | Finish        |
|----------------|--------|--------|------------------|------------|------------|---------------|
| 27230-072      | 553mm  | 800mm  | 1                | Black Grey | RAL 7021   | Powder Coated |
| 27230-070      | 553mm  | 500mm  | 1                | Black Grey | RAL 7021   | Powder Coated |
| 27230-080      | 1000mm | 1000mm | 1                | Black Grey | RAL 7021   | Powder Coated |
| 27230-076      | 900mm  | 900mm  | 1                | Black Grey | RAL 7021   | Powder Coated |
| 27230-071      | 553mm  | 600mm  | 1                | Black Grey | RAL 7021   | Powder Coated |

Table 2/2

| Catalog Number | Type        |
|----------------|-------------|
| 27230-072      | Base Plinth |
| 27230-070      | Base Plinth |
| 27230-080      | Base Plinth |
| 27230-076      | Base Plinth |
| 27230-071      | Base Plinth |

## ADDITIONAL PRODUCT DETAILS

---

Please order brush strip separately.

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**