


PropacPRO Rear Panel, Full Width, Unshielded

The rear panel, full width for PropacPRO Case mounts to the frame of the case. With or without vented slots.

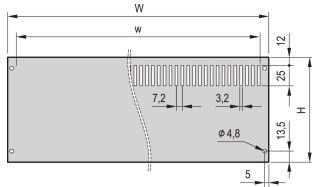

CERTIFICATIONS



FEATURES

Alu panel, 2.0 mm (84 HP 2.5 mm)

Mounting with support bracket on case (right and left)

SPECIFICATIONS

Material:	Aluminum
Finish:	Anodized
Works With:	Cases
Product Family:	PropacPRO
Type:	Rear Panel
Product Type:	Side Panel

Table 1/2

Catalog Number	Rack Height	Rack Width	Design Feature	Package Quantity
24576-153	4U	63HP	Perforated	1
24576-145	2U	63HP	Perforated	1
24576-050	3U	84HP	Non-Perforated	1
24576-149	3U	63HP	Perforated	1
24576-150	3U	84HP	Perforated	1

Catalog Number	Rack Height	Rack Width	Design Feature	Package Quantity
24576-049	3U	63HP	Non-Perforated	1
24576-052	4U	42HP	Non-Perforated	1
24576-148	3U	42HP	Perforated	1
24576-045	2U	63HP	Non-Perforated	1
24576-152	4U	42HP	Perforated	1
24576-053	4U	63HP	Non-Perforated	1
24576-047	3U	28HP	Non-Perforated	1
24576-054	4U	84HP	Non-Perforated	1
24576-048	3U	42HP	Non-Perforated	1
24576-154	4U	84HP	Perforated	1
24576-146	2U	84HP	Perforated	1
24576-044	2U	42HP	Non-Perforated	1
24576-046	2U	84HP	Non-Perforated	1
24576-158	6U	84HP	Perforated	1
24576-147	3U	28HP	Perforated	1

Table 2/2

Catalog Number	Rack Height	Rack Width	Design Feature	Package Quantity
24576-058	6U	84HP	Non-Perforated	1
24576-144	2U	42HP	Perforated	1

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE