

# Pipe/Cable Clamp



## FEATURES

Captive threaded stud minimizes the need for additional hardware

With the UNICBAND Sign Support Bracket and Fixoband Strap, attachments to pipe and pole can be made

## SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	Material	Finish	NB/DN	Outer Diameter (OD)	Width (W)
CR037HD	336300	Steel	Hot-Dip Galvanized	10	16 - 20 mm	16 mm
CR037S4	336400	Stainless Steel 304 (EN 1.4301)		10	16 - 20 mm	16 mm
CR050HD	336310	Steel	Hot-Dip Galvanized	15	20 - 25 mm	16 mm
CR050S4	336410	Stainless Steel 304 (EN 1.4301)		15	20 - 25 mm	16 mm
CR087S4	336422	Stainless Steel 304 (EN 1.4301)			32 - 34 mm	16 mm
CR087HD	336322	Steel	Hot-Dip Galvanized		32 - 34 mm	16 mm
CR075S4	336420	Stainless Steel 304 (EN 1.4301)		20	26.9 - 31.8 mm	16 mm


Catalog Number	Article Number	Material	Finish	NB/DN	Outer Diameter (OD)	Width (W)
CR075HD	336320	Steel	Hot-Dip Galvanized	20	26.9 - 31.8 mm	16 mm
CR150S4	336450	Stainless Steel 304 (EN 1.4301)		40	47 - 51 mm	20 mm
CR200S4	336460	Stainless Steel 304 (EN 1.4301)		50	59.2 - 63.5 mm	20 mm
CR100S4	336430	Stainless Steel 304 (EN 1.4301)		25	33.7 - 38 mm	20 mm
CR150HD	336350	Steel	Hot-Dip Galvanized	40	47 - 51 mm	20 mm
CR125HD	336340	Steel	Hot-Dip Galvanized	32	40.0 - 44.5 mm	20 mm
CR125S4	336440	Stainless Steel 304 (EN 1.4301)		32	40.0 - 44.5 mm	20 mm
CR200HD	336360	Steel	Hot-Dip Galvanized	50	59.2 - 63.5 mm	20 mm
CR100HD	336330	Steel	Hot-Dip Galvanized	25	33.7 - 38 mm	20 mm

Table 2/2

Catalog Number	Article Number	Static Load 1 (F1)	Static Load 2 (F2)
CR037HD	336300	125N	550N
CR037S4	336400	125N	550N
CR050HD	336310	125N	550N
CR050S4	336410	125N	550N
CR087S4	336422	125N	550N
CR087HD	336322	125N	550N
CR075S4	336420	125N	550N
CR075HD	336320	125N	550N
CR150S4	336450	250N	550N
CR200S4	336460	250N	550N
CR100S4	336430	250N	550N
CR150HD	336350	250N	550N
CR125HD	336340	250N	550N
CR125S4	336440	250N	550N

Catalog Number	Article Number	Static Load 1 (F1)	Static Load 2 (F2)
CR200HD	336360	250N	550N
CR100HD	336330	250N	550N

## DIAGRAMS

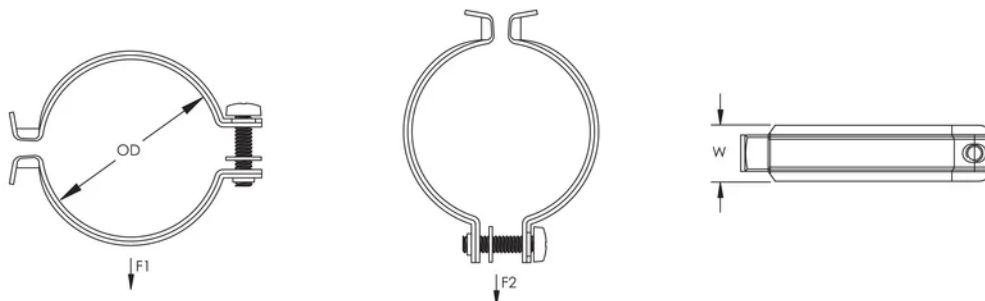

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

