


Vertical Adjustable Coupler

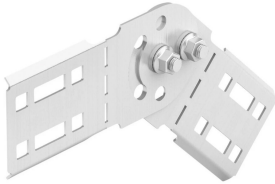

CERTIFICATIONS



FEATURES

Provides high-strength joint with SPEEDWAY Cable Ladder profile

Integral hinge allows simple vertical cable ladder joint adjustments

Installs quickly and easily with included hardware

Multiple slots allow for field adjustments

SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	Material	Finish	Angle (a)	A	B
CLSW4VACGA	842030	Steel	Hot-Dip Galvanized	0 - 90 °	150 mm	62 mm

Table 2/2

Catalog Number	Article Number	C
CLSW4VACGA	842030	2 mm

DIAGRAMS

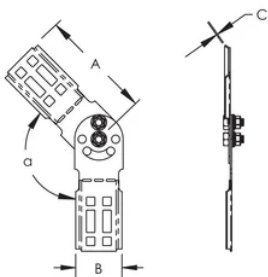

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

