


# Four Pole Distrib. Block with Threaded Bars, 400 A

## Data Solutions

### CATALOG NUMBER

---

**TR-400A**

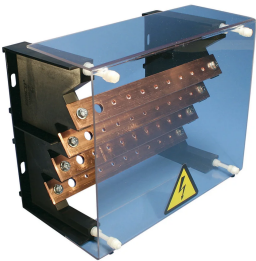

### CERTIFICATIONS

---



### FEATURES

---

Easily fixes onto DIN rail or mounts with screws

Bolts included for output connections

Transparent protection cover

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

### PRODUCT ATTRIBUTES

---

Article Number: 562010

Material: Copper; Glass Fibre Reinforced Polyamide; Plexiglass

Max Working Voltage, IEC (Ui): 1000

Peak Short Circuit Current (Ipk): 34kA

Short Term Withstand Current (Icw) 1s: 28kA

Line Side Number of Connections: 1

Load Side Number of Connections: 8

Hole Size (HS): 12mm

Thread Size (TS): M6

Depth (D): 140mm

Height (H): 240mm

Width (W): 300mm

Unit Weight: 2.83kg

Flammability Rating: UL® 94V-0

Complies With: IEC® 60439.1; IEC® 61439.1; IEC® 60695-2-11 (Glow Wire Test 960 °C)


## ADDITIONAL PRODUCT DETAILS

---

Line side and load side number of connections are per pole.

## DIAGRAMS

---

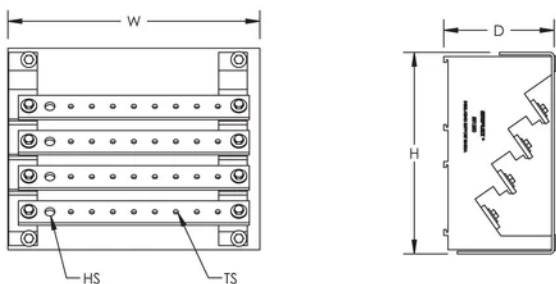

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**