

# Cavity Plug



## FEATURES

For use in plasterboard, hollow brick, hollow block and chipboard

Ideal for attachment to cavity walls

Large seating area for high loading capacity

## SPECIFICATIONS

**Finish:** Electrogalvanized

**Material:** Steel

**Screw Included:** Yes

Table 1/2

Catalog Number	Article Number	Screw Diameter (Sc)	Screw Length (L)	Drill Bit Diameter	Drill Bit Diameter	A
MFV433	571460	4	41mm	8mm	8mm	3 - 10 mm
MFV537	571470	5	46mm	10mm	10mm	5 - 14 mm
MFV650	571510	6	59mm	12mm	12mm	6 - 17 mm

Table 2/2

Catalog Number	Article Number	B	Ultimate Static Load 1 (F1)	Ultimate Static Load 2 (F2)
MFV433	571460	12 mm	200N	200N
MFV537	571470	12 mm	200N	200N
MFV650	571510	21 mm	200N	250N


## ADDITIONAL PRODUCT DETAILS

---

Refer to Ultimate Static Load 1 when anchor is set in plasterboard. Refer to Ultimate Static Load 2 when anchor is set in hollow block or hollow cinder block.

## DIAGRAMS

---

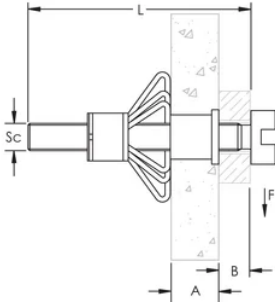

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

