


# ATCA Front Panel, St, Reinforced, With Spring

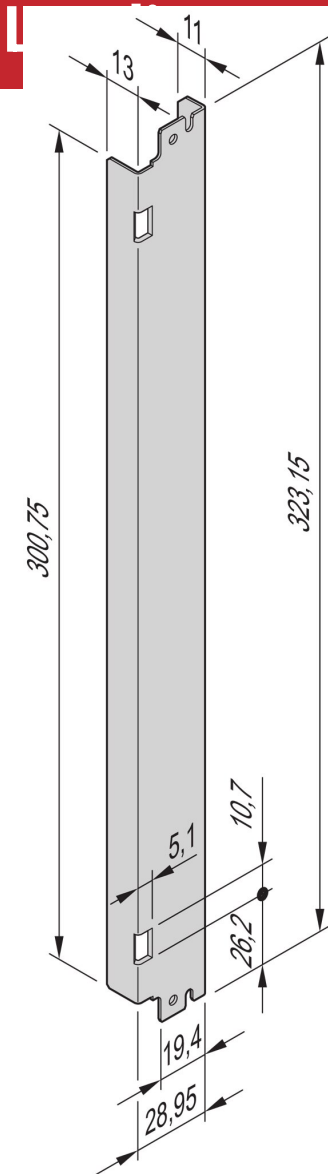

AdvancedTCA front panel for spring-loaded IEA handle with die-cast end piece.

## CERTIFICATIONS



## FEATURES

Configuration: Front panel with IEA handle (with/without spring loading)


## SPECIFICATIONS

<b>Depth (D):</b>	1mm
<b>Rack Width:</b>	6HP
<b>Rack Height:</b>	8U
<b>Accessory Type:</b>	Front panel
<b>Product Type:</b>	Front Panel
<b>Material:</b>	Stainless Steel

Table 1/1

Catalog Number	Package Quantity	Handle Type	Front Finish	Rear Finish	Height (H)	Width (W)
31596-791	1	Plunger	Raw	Raw	323.15mm	29mm
31596-792	1	Lever	Raw	Raw	323.15mm	29mm

## DIAGRAMS

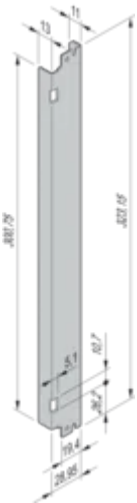

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**