


# PropacPRO Front Hood

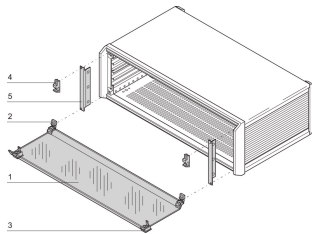

The front hood bottom hinged can be assembled on to a PropacPRO case. It protects the PCB from accidental operations. A retrofittable lock can be installed.

## CERTIFICATIONS



## FEATURES

Mounting of hinges at top or bottom

Lock (max. 2) retrofittable

From acrylic glass, hinged, removable

Lateral cover (item 5) also serves as vertical EMC shielding of side panels

## SPECIFICATIONS

- Rack Height:** 3U
- Works With:** Cases
- Product Type:** Cover Plate
- Type:** Front Hood
- Product Family:** PropacPRO
- Material:** Thermoplastic

Table 1/1

| Catalog Number | Rack Width | Package Quantity | Depth |
|----------------|------------|------------------|-------|
| 24576-080      | 28HP       | 1                |       |
| 24576-083      | 84HP       | 1                | 175mm |
| 24576-082      | 63HP       | 1                |       |

| Catalog Number | Rack Width | Package Quantity | Depth |
|----------------|------------|------------------|-------|
| 24576-081      | 42HP       | 1                |       |

## ADDITIONAL PRODUCT DETAILS

Cannot be combined with design elements.

Other heights available on request.

Before assembly of hood feet must be fixed to case; please order separately.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**