

# APY External Horizontal Wall Bracket



## FEATURES

Side mount saddle support for C-Profiles and strut

Complete with fixings

## SPECIFICATIONS

Table 1/3

Catalog Number	Article Number	E-Number	Material	Finish	Channel Type	Strut Type
APYSTRUTS6	584840		Stainless Steel 316 (EN 1.4401)			A (41 x 41 mm), C (21 x 41 mm)
APYE23EG	584740		Steel	Electrogalvanized	E2L, E2, E3	
APYE4STRUTEG	584751	3532059	Steel	Electrogalvanized	E4	A (41 x 41 mm), C (21 x 41 mm)
APYE01EG	584758		Steel	Electrogalvanized	E0L, E0, E1	

Table 2/3


Catalog Number	Article Number	E-Number	Height (H)	Width (W)	Thickness (T)	A
APYSTRUTS6	584840		50 mm	144 mm	5 mm	43 mm
APYE23EG	584740		40 mm	124 mm	5 mm	36 mm
APYE4STRUTEG	584751	3532059	50 mm	144 mm	5 mm	43 mm

Catalog Number	Article Number	E-Number	Height (H)	Width (W)	Thickness (T)	A
APYE01EG	584758		40 mm	124 mm	5 mm	31 mm

Table 3/3

Catalog Number	Article Number	E-Number	B	C
APYSTRUTS6	584840		12 mm	19 mm
APYE23EG	584740		12 mm	19 mm
APYE4STRUTEG	584751	3532059	12 mm	19 mm
APYE01EG	584758		12 mm	19 mm

## DIAGRAMS

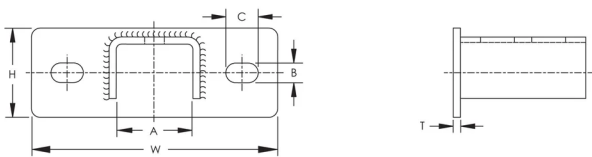

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

