

KN Hook



FEATURES

Use to repair a link or combine two chains together by hammering the link shut

SPECIFICATIONS


Finish: Electrogalvanized

Material: Steel

Table 1/1

Catalog Number	Article Number	E-Number	Diameter (Ø)	Length (L)	B	Static Load
KN30EG	380050	1319828	3 mm	16.5mm	12.5 mm	370N
KN40EG	380060	1341094	4 mm	20mm	16 mm	550N
KN50EG	380070	1319829	5 mm	23mm	20 mm	950N

DIAGRAMS

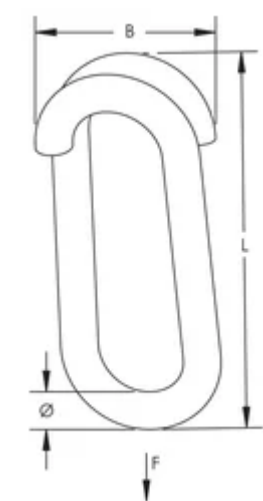

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

