

# SOB Pipe Clamp for PVC Pipe, 300 DN, 316 mm OD

## CATALOG NUMBER

**SOB300PVCPPC**



## FEATURES

Stand off bracket for vertical pipe services

Attaches directly to horizontal or vertical structural member

Double bolted

## PRODUCT ATTRIBUTES

Material: Steel

Finish: Polyester

Color: White

NB/DN: 300

Outer Diameter (OD): 316 mm

A: 435 mm

Width (W): 40 mm

Thickness (T): 6 mm


Hole Size (HS): 13.5 mm

Screw Diameter (Sc): 12

Screw Length (L): 40mm

Static Load: 7500N

DIAGRAMS

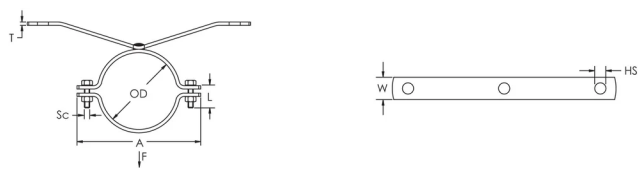

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

