

FleXbus Transformer Cover IP2X for 1 Conductor per Phase

Data Solutions

CATALOG NUMBER

FLEXCOVIP2XONE



CERTIFICATIONS



FEATURES

Input/output for neutral/ground conductor

Resistance to solvent and hydrocarbon splashes

Installs quickly and easily

UV resistance

PRODUCT ATTRIBUTES

Article Number: 508160

Material: Polyvinylchloride

Working Temperature: -40 to 140°C


Length (L): 465mm

Width (W): 182mm

Depth (D): 126mm

Unit Weight: 0.53kg

DIAGRAMS

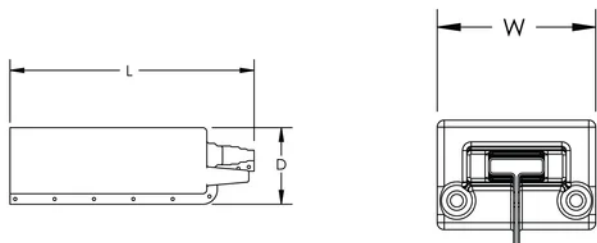

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE