


# 19" Front Panel, 2 U, 3 mm, Al, RAL7035

## Data Solutions

### CATALOG NUMBER

**30118-301**

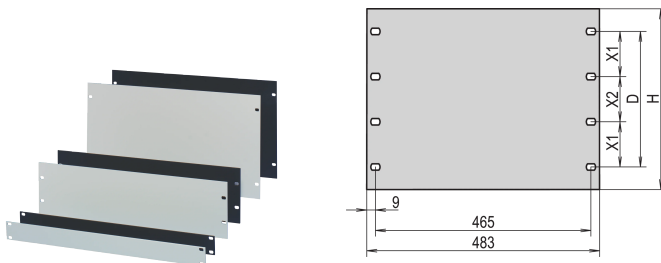

Front panels made of Aluminum.

### CERTIFICATIONS



### FEATURES

Aluminum, 4 or 3 mm thick, with Anodized or Painted finish

### PRODUCT ATTRIBUTES

Rack Height: 2U

Depth (D): 3mm

Accessory Type: Front panel

Mounting: Screw-on Front

Finish: Powder Coated

Front Finish: Painted

Package Quantity: 1

Color Code: RAL 7035

Height (H): 88.1mm

Product Type: Front Panel

Type: 19" Front Panel

Net Weight: 0.35kg

Please order 19" assembly kit separately.

Technical drawing of a rectangular plate with dimensions and hole positions. The plate has a width of 483 and a height of H. There are four holes along the top edge, with a center-to-center distance of 465 between the first and last holes. The distance from the left edge to the center of the first hole is g. The distance from the center of the first hole to the center of the second hole is x1. The distance from the center of the second hole to the center of the third hole is x2. The distance from the center of the third hole to the center of the fourth hole is x1. The distance from the center of the fourth hole to the right edge is g.

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**