


# CPCI Bridge, 32-Bit, 33 MHz

## CATALOG NUMBER

**23006-920**

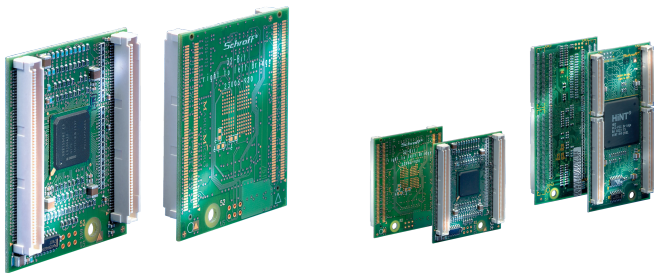

Very compact and low bridge shape, no interference with rear transition boards

## CERTIFICATIONS



## FEATURES

Bridge is designed for primary backplanes with system slot right; bridge for system slot left available on request

33 MHz capable

Bridge mounted on rear of backplane, hence no loss of slots

In accordance with: PICMG 2.6 CompactPCI Bridging Specification, PCI 2.1 PCI Local Bus Specification, Rev. 2.1

## PRODUCT ATTRIBUTES

Product Type: Backplane

Backplane Type: CompactPCI Bridge, 32-bit, 33 MHz

System Slot: Right

Net Weight: 0.028kg

Package Quantity: 1

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Europe**

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Asia**

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Middle East & India**

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**