


# PropacPRO Rear Panel, Full Width, Unshielded

The rear panel, full width for PropacPRO Case mounts to the frame of the case. With or without vented slots.

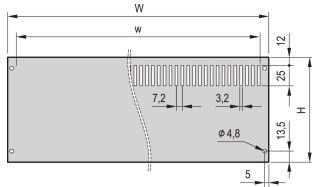

## CERTIFICATIONS



## FEATURES

Alu panel, 2.0 mm (84 HP 2.5 mm)

Mounting with support bracket on case (right and left)

## SPECIFICATIONS

<b>Material:</b>	Aluminum
<b>Finish:</b>	Anodized
<b>Works With:</b>	Cases
<b>Product Family:</b>	PropacPRO
<b>Type:</b>	Rear Panel
<b>Product Type:</b>	Side Panel

Table 1/2

Catalog Number	Rack Height	Rack Width	Design Feature	Package Quantity
24576-153	4U	63HP	Perforated	1
24576-145	2U	63HP	Perforated	1
24576-050	3U	84HP	Non-Perforated	1
24576-149	3U	63HP	Perforated	1
24576-150	3U	84HP	Perforated	1

Catalog Number	Rack Height	Rack Width	Design Feature	Package Quantity
24576-049	3U	63HP	Non-Perforated	1
24576-052	4U	42HP	Non-Perforated	1
24576-148	3U	42HP	Perforated	1
24576-045	2U	63HP	Non-Perforated	1
24576-152	4U	42HP	Perforated	1
24576-053	4U	63HP	Non-Perforated	1
24576-047	3U	28HP	Non-Perforated	1
24576-054	4U	84HP	Non-Perforated	1
24576-048	3U	42HP	Non-Perforated	1
24576-154	4U	84HP	Perforated	1
24576-146	2U	84HP	Perforated	1
24576-044	2U	42HP	Non-Perforated	1
24576-046	2U	84HP	Non-Perforated	1
24576-158	6U	84HP	Perforated	1
24576-147	3U	28HP	Perforated	1

Table 2/2

Catalog Number	Rack Height	Rack Width	Design Feature	Package Quantity
24576-058	6U	84HP	Non-Perforated	1
24576-144	2U	42HP	Perforated	1

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**