


# Front Panel With AC Input Module

Front Panel for CompactPCI Systems with mounted Wide Range AC Input Module containing AC Plug, Fuse Holder and EMC Filter.

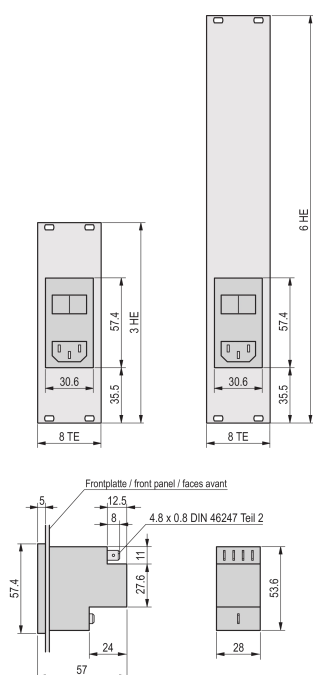

## CERTIFICATIONS



## FEATURES

Voltage 110 VAC ... 250 VAC, 50 Hz ... 60 Hz

Front panel for shielding with EMC textile gasket

Max. current 10 A at 40°C

## SPECIFICATIONS

**Accessory Type:** Front panel

Table 1/2

| Catalog Number | Material | Front Finish | Rear Finish | Rack Height | Height | Rack Width |
|----------------|----------|--------------|-------------|-------------|--------|------------|
|----------------|----------|--------------|-------------|-------------|--------|------------|

|           |          |          |            |    |          |     |
|-----------|----------|----------|------------|----|----------|-----|
| 24579-059 | Aluminum | Anodized | Anodized   | 3U | 261.75mm | 8HP |
| 24579-058 | Aluminum | Anodized | Conductive | 3U | 128.4mm  | 8HP |

| Table 2/2      |        |       |                  |          |  |
|----------------|--------|-------|------------------|----------|--|
| Catalog Number | Width  | Depth | Package Quantity | Finish   |  |
| 24579-059      | 40.3mm | 2.5mm | 1                | Anodized |  |
| 24579-058      | 40.3mm | 2.5mm | 1                | Anodized |  |

## ADDITIONAL PRODUCT DETAILS

EMC profile seals are required to shield the front panels.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**