

# S Hook



## FEATURES

For suspending chains, perforated bands, and similar items

## SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	E-Number	Material	Finish	Diameter (Ø)	Length (L)
S30EG	591570	7994062	Steel	Electrogalvanized	3 mm	25mm
S40S4	591650		Stainless Steel 304 (EN 1.4301)		4 mm	35mm
S40EGSP25	172420	7994063	Steel	Electrogalvanized	4 mm	35mm
S40EG	591580	7994064	Steel	Electrogalvanized	4 mm	35mm
S50EG	591590		Steel	Electrogalvanized	5 mm	45mm
S50S4	591660		Stainless Steel 304 (EN 1.4301)		5 mm	45mm

Table 2/2

Catalog Number	Article Number	E-Number	Static Load
S30EG	591570	7994062	120N

Catalog Number	Article Number	E-Number	Static Load
S40S4	591650		250N
S40EGSP25	172420	7994063	250N
S40EG	591580	7994064	250N
S50EG	591590		400N
S50S4	591660		400N

## DIAGRAMS

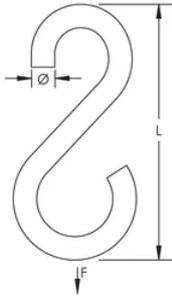

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

