

APY External Horizontal Wall Bracket



FEATURES

Side mount saddle support for C-Profiles and strut

Complete with fixings

SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	Material	Finish	Channel Type	Strut Type	Height (H)
APYSTRUTS6	584840	Stainless Steel 316 (EN 1.4401)			A (41 x 41 mm), C (21 x 41 mm)	50 mm
APYE23EG	584740	Steel	Electrogalvanized	E2L, E2, E3		40 mm
APYE4STRUTEG	584751	Steel	Electrogalvanized	E4	A (41 x 41 mm), C (21 x 41 mm)	50 mm
APYE01EG	584758	Steel	Electrogalvanized	E0L, E0, E1		40 mm

Table 2/2

Catalog Number	Article Number	Width (W)	Thickness (T)	A	B	C
APYSTRUTS6	584840	144 mm	5 mm	43 mm	12 mm	19 mm
APYE23EG	584740	124 mm	5 mm	36 mm	12 mm	19 mm
APYE4STRUTEG	584751	144 mm	5 mm	43 mm	12 mm	19 mm

CatalogNumber	Article Number	Width (W)	Thickness (T)	A	B	C
APYE01EG	584758	124 mm	5 mm	31 mm	12 mm	19 mm

DIAGRAMS

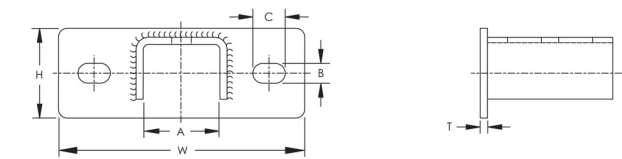

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

