

MC/AC Cable Support Bracket



CERTIFICATIONS



BABA



FEATURES

Neatly isolates, supports and secures MC/AC cables

Properly spaces MC/AC cable to help eliminate bundling and NEC® & CEC derating issues

Results in a "neat and workmanlike" installation

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2

Catalog Number	Isolated Ground Cable Size	MC/AC Cable Size	Super Neutral Cable Size	Cable Capacity	Hole Size 1 (HS1)	Hole Size 2 (HS2)
MCS101	12-3 to 8-2	10-3 to 8-3	12-3 to 10-2	7	1/4"	0.2"
MCS50		14-3 to 10-2	10-2	4	1/4"	0.2"

CatalogNumber	IsolatedGround CableSize	MC/AC Cable Size	Super Neutral Cable Size	Cable Capacity	Hole Size 1 (HS1)	Hole Size 2 (HS2)
MCS100		14-3 to 10-2	10-2	8	1/4"	0.2"


Table 2/2

Catalog Number	Outer Diameter (OD)
MCS101	0.560" - 0.69"
MCS50	0.430" - 0.56"
MCS100	0.430" - 0.56"

ADDITIONAL PRODUCT DETAILS

4Z parts installed on 3/8" (M10) smooth rod in the F2 direction has a Static Load Rating of 15 lb (67 N).

DIAGRAMS

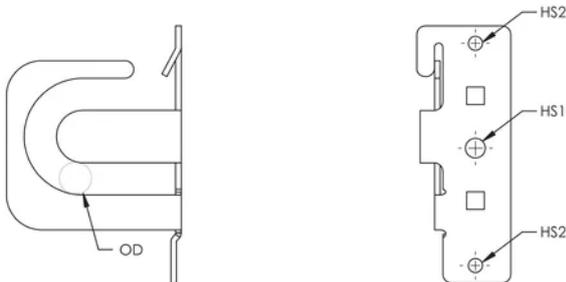

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

