


# MTCA.0 System for 2 Single Full-Size AMC Modules, 1 HE

## CATALOG NUMBER

**11850-023**

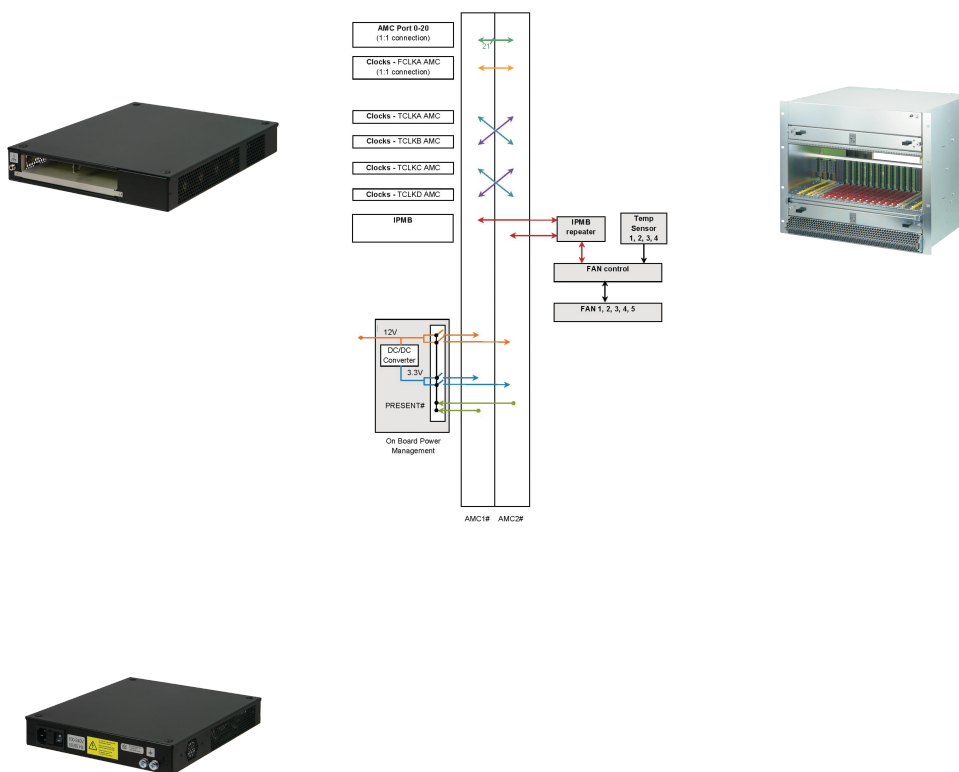

The System is designed for 2 AMC modules. The integrated Power Supply and Power switches on the backplane enable the Payload Power to the AMC Modules without the need for a separate MCH.

## CERTIFICATIONS



## FEATURES

- Small, compact case to hold 2 single full-size AdvancedMC modules With an optional 2 HP filler module, 2 single mid-size modules can also be fitted
- Direct connection of all ports between both AdvancedMC slots (see backplane topology); data transfer rates up to 10 Gbps per port
- 90 - 264 VAC wide range input on rear of case, 150 W power supply in rear section of enclosure
- 12 VDC voltage is activated by the AdvancedMC module presence signal
- 150 W cooling capacity at an ambient temperature of 55 °C, airflow from right to left, temperature-regulated fans
- Fan unit and fan filter are easy to service or replace
- The enclosure is stackable and prepared for plate mounting

## PRODUCT ATTRIBUTES

|                                                    |
|----------------------------------------------------|
| Product Type: System                               |
| Number of Slots: 2                                 |
| Type: Pico System                                  |
| Backplane Type: All Ports Point to Point Connected |
| Data Transfer: 40 GbE; PCIe Gen3                   |
| Power per Slot: 60W                                |
| Input Voltage AC: 100 – 240V                       |
| Airflow Direction: Right to Left                   |
| Rack Height: 1U                                    |
| Power Supply Type: Open Frame                      |
| Power Supply Included: Yes                         |
| Rear I/O: No                                       |
| Complies With: PICMG MTCA.0 R2.0                   |
| Package Quantity: 1                                |

## ADDITIONAL PRODUCT DETAILS

- Modified systems available on request.
- Completely assembled, wired and tested.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**