


Door Contact Switch Without Cable

Data Solutions

CATALOG NUMBER

20118-810

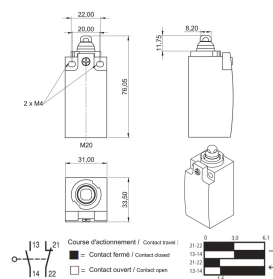

Door contact switch with magnetic contact, allows operational efficiency. This product is easy handlable by plug and play.

CERTIFICATIONS



FEATURES

Door contact switch (without connection cable)

PRODUCT ATTRIBUTES

Product Type: Switch

Depth: 33.5mm

Height: 76.5mm

Operating Temperature: -25 to 75°C

Protection Rating: IP66

Width: 31mm

Complies With: UL® 508; EN 50047 form B

Current Rating: 3 – 6A

Gross Weight: 0.1kg

Package Quantity: 1

Voltage: 24 – 230V

Wire Size: 0.5 – 2.5mm²

ADDITIONAL PRODUCT DETAILS

Please order bracket for installation of door switch (Varistar, Novastar, Eurorack) separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRachte