

CAPB Cap Nut with Threaded Stud



CERTIFICATIONS



FEATURES

For use with DH Distance Holder and Spacer


SPECIFICATIONS

Temperature:	80 °C Max
Finish:	Electrogalvanized
Material:	Steel;Polystyrene
Flammability Rating:	UL® 94HB

Table 1/1

Catalog Number	Article Number	Thread Size (TS)	Thread Length (TL)	Height (H)	Width (W)	Unit Weight
CAP-CAPB6	560850	M6	8mm	12 mm	14 mm	0 kg
CAP-CAPB5	560840	M5	8mm	12 mm	14 mm	0 kg

DIAGRAMS

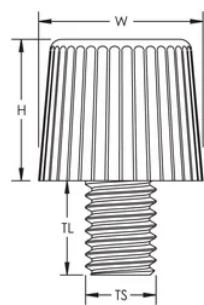

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE