


Comptec GND/Jordingssett

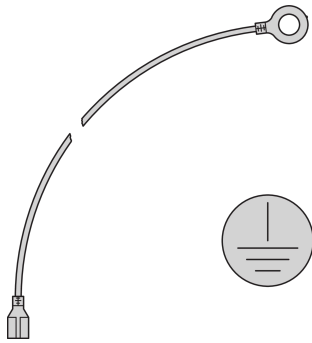

Beskyttende GND/jordingskoblinger i samsvar med: DIN EN 50178, VDE 0160/DEN 62368-1, VDE 0805 DIN EN 61010?1, VDE 0411 DEL 1 DIN EN 61010?1A2, VDE 0411 DEL 1/A1.

SERTIFISERINGER



FUNKSJONER

Beskyttende GND/jordingskoblinger i samsvar med: DIN EN 50178/VDE 0160 DIN EN 62368-1/VDE 0805 DIN EN 61010?1 /VDE 0411 DEL 1 DIN EN 61010?1A2 /VDE 0411 DEL 1/A1

VDE-testet

SPESIFIKASJONER

Produktserie: Comptec
Type: Jordingssett
Produkttype: Jordingssett

Table 1/1

Katalognummer	Antall pakker	Fungerer med
21100-490	1	Esker, Ståldeksel
21100-448	1	Esker, Ståldeksel
21100-347	1	Esker, Aluminiumsdeksel

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE