

# nVent CADDY Cat CM U-Hook, 203 mm

## Data Solutions

### NÚMERO DE CATÁLOGO

---

**CAT200CMLN**



### CERTIFICATIONS

---



### CARACTERÍSTICAS

---

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic

System offers a convenient pathway for wires and cables

Specially designed U-Hooks have large-diameter, rounded support surfaces

U-Hooks can be mounted vertically along the same drop rod to create a tree configuration

Cantilever mounting allows U-Hooks to be mounted to walls and columns with brackets

Rounded edges help prevent over-bending and kinking of cables

Ideal for retrofit applications where cable runs need to be routed around existing building infrastructure

Compliant with NEC® and ANSI®/TIA structured cabling systems standards

### CARATERÍSTICAS DO PRODUTO

---

Material: Aço

Acabamento: Electrogalvanized

Cable Capacity, Cat 5e: 450

Cable Capacity, Cat 6: 350

Cable Capacity, Cat 6A: 215

A: 203mm


Area: 533mm<sup>2</sup>

Tamanho do orifício (HS): 9.5mm

Static Load: 440N

## DIAGRAMAS

---

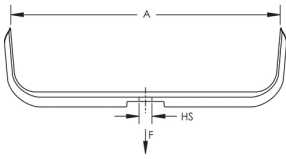

## AVISO

---

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em [www.nVent.com](http://www.nVent.com) e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.



O nosso forte portfólio de marcas:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**