

# nVent CADDY Cat HP J-Hook with Z Purlin Clip, 50 mm dia, 1.5–6 mm Flange

## Data Solutions

### NÚMERO DE CATÁLOGO

**CAT32HPAF14**



### CERTIFICATIONS



### CARACTERÍSTICAS

Hammer-on or install from the floor with the VAFT tool

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic

Provides superior fill capacity and load rating over most other non-continuous cable support alternatives

Rounded edges on J-Hooks provide proper bend radius support for high performance data cables

Cost effective alternative to expensive cable tray

Complies with EN 50174-2

Meets ISO®/IEC 14763-2, ANSI®/TIA 568 and ANSI®/TIA 569

### CARATERÍSTICAS DO PRODUTO

Número do artigo: 181142

Material: Aço; Spring Aço

Acabamento: Pregalvanized; nVent CADDY Armour

Diâmetro (Ø): 50mm

Area: 2561mm<sup>2</sup>

Cable Capacity, Cat 5e: 90

Cable Capacity, Cat 6: 60

Cable Capacity, Cat 6A: 35

Espessura do flange (FT): 1.5 – 6mm


Static Load: 270N

## DETALHES ADICIONAIS DO PRODUTO

Non-continuous supports may not exceed spacing of 5' (1.5 m) per TIA 569-C.9.7 and EN 50174-2.

Cable capacity is calculated based on a 70% fill rate.

## DIAGRAMAS

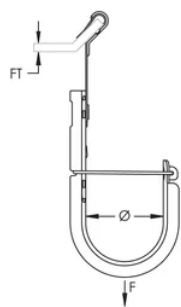

## AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em [www.nVent.com](http://www.nVent.com) e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.



O nosso forte portfólio de marcas:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**