

nVent CADDY Cat 425 Adjustable Cable Support with BC200 Beam Clamp, 100 mm, 150 mm dia

Data Solutions

NÚMERO DE CATÁLOGO

CAT425BC200



CERTIFICATIONS



CARACTERÍSTICAS

Easy installation to beam flanges

Rotates 360 degrees to support various directional runs of cable

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic

Simple unlocking and locking of bar allows for additional cables to be added easily after installation

Adjustable strap allows for multiple support sizes to reduce inventory

Cost effective alternative to expensive cable tray

cULus® Listed and complies with NEC® and TIA requirements for structured cabling systems

Suitable for air handling spaces (plenum)

CARACTERÍSTICAS DO PRODUTO

Número do artigo: 181460

Material: Aço; Polietileno

Acabamento: Electrogalvanized

Diâmetro (Ø): 100mm; 150mm

Area: 13181mm²

Cable Capacity, Cat 5e: 425

Cable Capacity, Cat 6: 325


Cable Capacity, Cat 6A: 210

Espessura do flange (FT): 3.2 – 12.7mm

Torque (TQ): 3N·m

Static Load: 450N

DIAGRAMAS

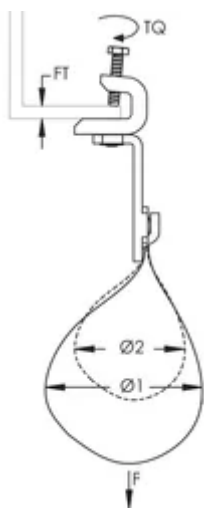

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.



O nosso forte portfólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE